

Part No: 868S-529C

Schedule 80 PVC & CPVC

Clamp-On Saddle

Desc: 6X2-1/2 CPVC CLAMP SADDLE D/O SOC EPDM S

MSRP: 513.31

Part Code: 096

Weight(lbs): 5.964

Weight(kg): 2.705

Weight(gm): 2705

Size: 6"X2-1/2"

Color: GRAY


Material: CPVC

Connection Double Socket

Type Clamp Saddle

Hardware SS

O-Ring EPDM

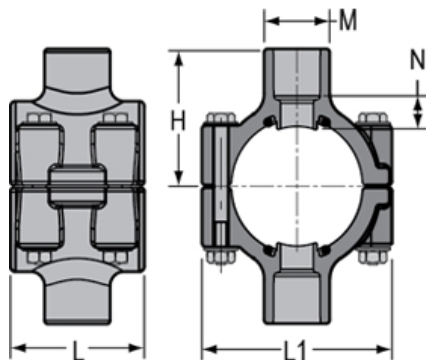

H = 6-9/32

L = 6

L1 = 8-3/16

M = 4-9/32

N = 7/8

Bolt = 10

No of = 4

Hole Size = 3

Torque
FT./LBS.

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Bushing Dimension References

