

Part No: 868S-578

Schedule 80 PVC & CPVC

Clamp-On Saddle

Desc: 8X2 PVC CLAMP SADDLE D/O SOC EPDM SS BLT

MSRP: 526.64

Part Code: 086

Weight(lbs): 8.27

Weight(kg): 3.751

Weight(gm): 3751

Size: 8"X2"

Color: GRAY


Material: PVC

Connection Double Socket

Type Clamp Saddle

Hardware SS

O-Ring EPDM

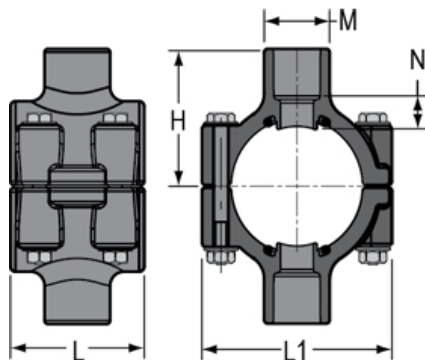

H = 6-1/2

L = 8- 1/2

L1 = 10-1/16

M = 3

N = 11/16

Hole Size = 2-1/8

Bolt = 10
Torque
FT./LBS.

No of = 6
Bolts

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Bushing Dimension References

