

Part No: 868S-585

Schedule 80 PVC & CPVC

Clamp-On Saddle

Desc: 8X6 PVC CLAMP SADDLE D/O SOC EPDM SS BLT

MSRP: 766.07

Part Code: 086

Weight(lbs): 11.572

Weight(kg): 5.249

Weight(gm): 5249

Size: 8"X6"

Color: GRAY


Material: PVC

Connection Double Socket

Type Clamp Saddle

Hardware SS

O-Ring EPDM

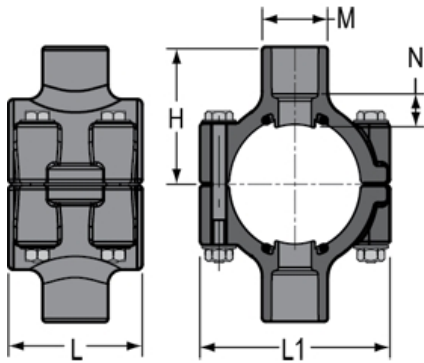

H = 8- 3/32

L = 8- 1/2

L1 = 10- 1/8

M = 7- 5/8

N = 11/16

Hole Size = 6

Bolt = 10

Torque
FT./LBS.

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

