

Part No: 868SV-338

Schedule 80 PVC & CPVC

Clamp-On Saddle

Desc: 3X2 PVC CLAMP SADDLE D/O SOC FKM SS BL

MSRP: 151.22

Part Code: 086

Weight(lbs): 1.51

Weight(kg): 0.685

Weight(gm): 685

Size: 3"X2"

Color: GRAY


Material: PVC

Connection Double Socket

Type Clamp Saddle

Hardware SS

O-Ring FKM

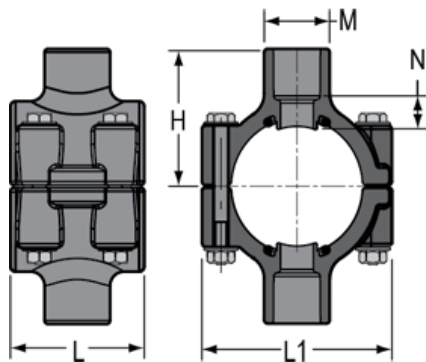

H = 3-11/16

L = 4-1/8

L1 = 4-3/4

M = 3

N = 3/8

Bolt = 8

Hole Size = 2-1/4

No of = 4

Bolts

Torque
FT./LBS.

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

