

Part No: 868SV-579

Schedule 80 PVC & CPVC

Clamp-On Saddle

Desc: 8X2-1/2 PVC CLAMP SADDLE D/O SOC FKM

MSRP: 616.81

Part Code: 086

Weight(lbs): 11.096

Weight(kg): 5.033

Weight(gm): 5033

Size: 8"X2-1/2"

Color: GRAY


Material: PVC

Connection Double Socket

Type Clamp Saddle

Hardware SS

O-Ring FKM

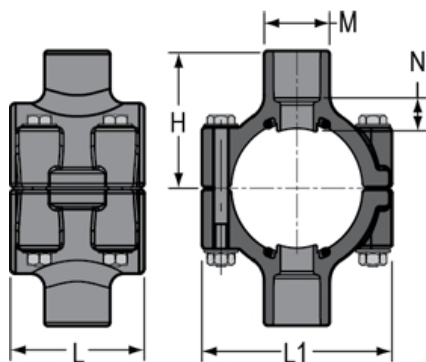

H = 7-5/8

L = 8- 1/2

L1 = 10-1/16

M = 5- 1/4

N = 1-1/2

Bolt = 10

Hole Size = 4

No of = 6

Bolts

Torque
FT./LBS.

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Bushing Dimension References

