

Part No: 868V-334

Schedule 80 PVC & CPVC

Clamp-On Saddle

Desc: 3X3/4 PVC CLAMP SADDLE D/O SOC FKM ZN

MSRP: 90.64

Part Code: 086

Weight(lbs): 0.933

Weight(kg): 0.423

Weight(gm): 423

Size: 3"X3/4"

Color: GRAY


Material: PVC

Connection Double Socket

Type Clamp Saddle

Hardware Zinc

O-Ring FKM

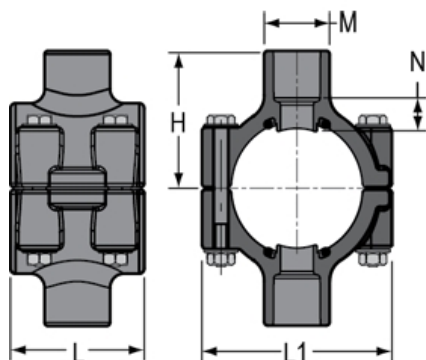

H = 3- 1/16

L = 3

L1 = 4- 5/8

M = 1- 3/8

N = 9/32

No of Bolts = 4

Bolt = 8
Torque
FT./LBS.

Hole Size = 7/8

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

