

Part No: 868V-338

Schedule 80 PVC & CPVC

Clamp-On Saddle

Desc: 3X2 PVC CLAMP SADDLE D/O SOC FKM ZN BL

MSRP: 90.64

Part Code: 086

Weight(lbs): 1.541

Weight(kg): 0.699

Weight(gm): 699

Size: 3"X2"

Color: GRAY


Material: PVC

Connection Double Socket

Type Clamp Saddle

Hardware Zinc

O-Ring FKM

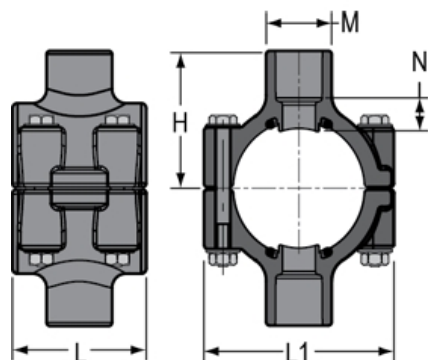

No of Bolts = 4

Bolt Torque = 8
FT./LBS.

Hole Size = 2-1/4

H = 3-7/8

L = 4-1/8

L1 = 4-3/4

M = 3

N = 3/8

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

