

Part No: 869-523SR

Schedule 80 PVC & CPVC

Clamp-On Saddle

Desc: 6X1/2 PVC CLAMP SADDLE D/O SRFPT EPDM ZN

MSRP: 197.91

Part Code: 086

Weight(lbs): 2.665

Weight(kg): 1.209

Weight(gm): 1209

Size: 6"X1/2"

Color: GRAY


Material: PVC

Connection Double SR Fipt

Type Clamp Saddle

Hardware Zinc

O-Ring EPDM

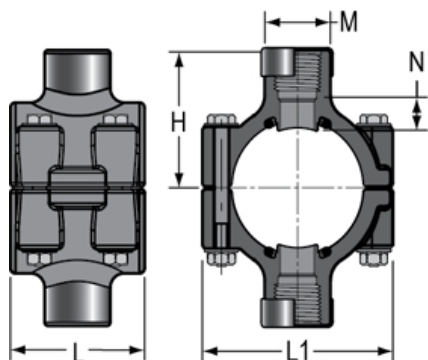

No of Bolts = 4

M = 1-23/32

N = 1-5/16

Hole Size = 1-1/8

Bolt Torque = 8
FT./LBS.

H = 5-11/32

L = 3

L1 = 8-3/16

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Bushing Dimension References

