

**Part No:** 869-524SR

**Schedule 80 PVC & CPVC**

**Clamp-On Saddle**

**Desc:** 6X3/4 PVC CLAMP SADDLE D/O SRFPT EPDM ZN

**MSRP:** 197.91

**Part Code:** 086

**Weight(lbs):** 2.639

**Weight(kg):** 1.197

**Weight(gm):** 1197

**Size:** 6"X3/4"

**Color:** GRAY


**Material:** PVC

**Connection** Double SR Fipt

**Type** Clamp Saddle

**Hardware** Zinc

**O-Ring** EPDM

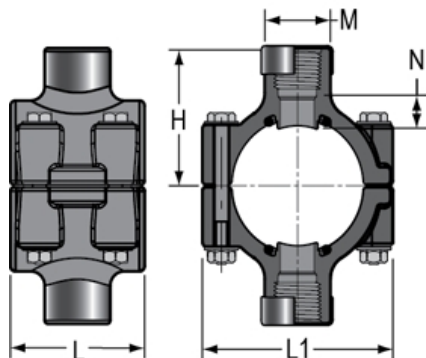

**H** = 5-3/8

**Hole Size** = 1-1/8

**Bolt** = 10  
**Torque**  
**FT./LBS.**

**No of** = 4  
**Bolts**

**L** = 3

**L1** = 8-3/16

**M** = 1-23/32

**N** = 1-11/32

## Injection Molded Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

**H** = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

**L** = Overall length of fittings; ± 1/16 inch.

**M** = Outside diameter of socket/thread hub; ± 1/16 inch.

**N** = Socket bottom to socket bottom; couplings; ± 1/16 inch.

**W** = Height of cap; ± 1/16 inch

## Typical Bushing Dimension References

