

Part No: 869-528CSR

Schedule 80 PVC & CPVC

Clamp-On Saddle

Desc: 6X2 CPVC CLAMP SADDLE D/O SRFPT EPDM ZN

MSRP: 344.7

Part Code: 096

Weight(lbs): 3.741

Weight(kg): 1.697

Weight(gm): 1697

Size: 6"X2"

Color: GRAY


Material: CPVC

Connection Double SR Fipt

Type Clamp Saddle

Hardware Zinc

O-Ring EPDM

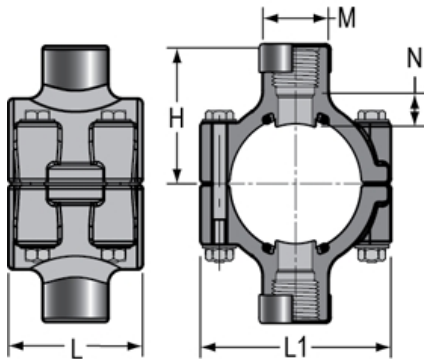

H = 5- 1/2

L = 4- 1/8

L1 = 8-3/16

M = 3-1/32

N = 1-3/16

Bolt = 10

Hole Size = 2-1/4

No of = 4

Bolts

Torque
FT./LBS.

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

