

Part No: 869-574SR

Schedule 80 PVC & CPVC

Clamp-On Saddle

Desc: 8X3/4 PVC CLAMP SADDLE D/O SRFPT EPDM ZN

MSRP: 425.54

Part Code: 086

Weight(lbs): 9.103

Weight(kg): 4.129

Weight(gm): 4129

Size: 8"X3/4"

Color: GRAY


Material: PVC

Connection Double SR Fipt

Type Clamp Saddle

Hardware Zinc

O-Ring EPDM

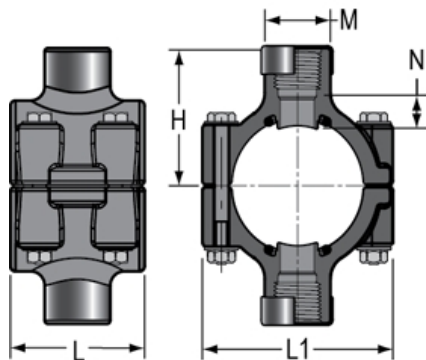

Hole Size = 2-1/8

Bolt = 10
Torque
FT./LBS.

No of = 6
Bolts

H = 6-15/16

L = 8- 1/2

L1 = 10-1/16

M = 3

N = 1-13/16

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Bushing Dimension References

