

Part No: 869-624CSR

Schedule 80 PVC & CPVC

Clamp-On Saddle

Desc: 10X4 CPVC CLAMP SADDLE D/O SRFPT EPDM ZN

MSRP: 972.4

Part Code: 096

Weight(lbs): 13.984

Weight(kg): 6.343

Weight(gm): 6343

Size: 10"X4"

Color: GRAY


Material: CPVC

Connection Double SR Fipt

Type Clamp Saddle

Hardware Zinc

O-Ring EPDM

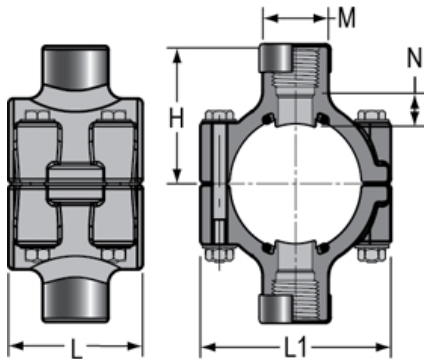

H = 8-7/16

L = 8- 1/2

L1 = 12-1/4

M = 5- 1/4

N = 1-17/32

Bolt = 10

Hole Size = 4

No of = 6

Bolts

Torque
FT./LBS.

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

