

Part No: 8698-032

Schedule 80 PVC & CPVC

Union

Desc: 32MMX1 PVC TRANS UNION EPDM PLN SOCXFPT

MSRP: 41.48

Part Code: 197

Weight(lbs): 0.287

Weight(kg): 0.13

Weight(gm): 130


Size: 32mmX1"

Color: GRAY

Material: PVC

Connection Din Socket x ASTM Fipt

O-Ring EPDM

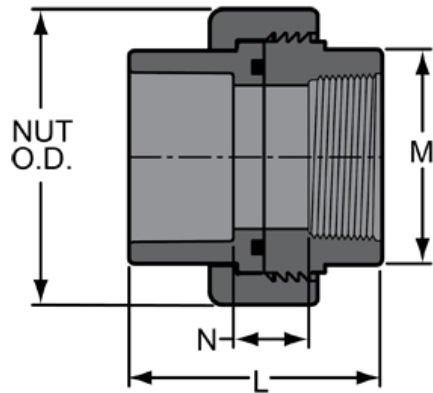

L = 2-25/32

M = 1-23/32

N = 13/16

NUT = 2-21/32
O.D.

M1 = 1-11/16

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

