

Part No: 8698-063

Schedule 80 PVC & CPVC

Union

Desc: 63MMX2 PVC TRANS UNION EPDM PLN SOCXFPT

MSRP: 150.9

Part Code: 197

Weight(lbs): 0.886

Weight(kg): 0.402

Weight(gm): 402


Size: 63mmX2"

Color: GRAY

Material: PVC

Connection Din Socket x ASTM Fipt

O-Ring EPDM

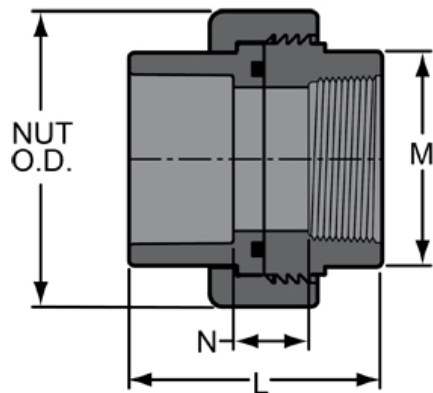

L = 3-11/16

M = 2-7/8

N = 1-3/16

NUT = 4-5/16
O.D.

M1 = 3

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

