

Part No: 869SV-335SR

Schedule 80 PVC & CPVC

Clamp-On Saddle

Desc: 3X1 PVC CLAMP SADDLE D/O SRFPT FKM SS

MSRP: 167.92

Part Code: 086

Weight(lbs): 0.99

Weight(kg): 0.449

Weight(gm): 449

Size: 3"X1"

Color: GRAY


Material: PVC

Connection Double SR Fipt

Type Clamp Saddle

Hardware SS

O-Ring FKM

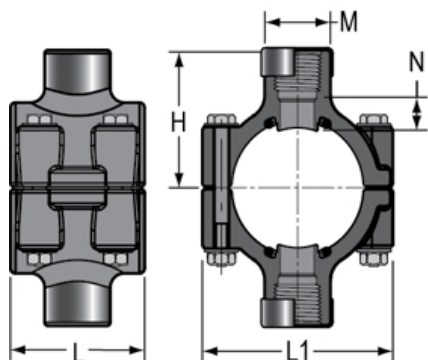

H = 3-3/16

L = 3

L1 = 4-3/4

M = 1-23/32

N = 17/32

No of Bolts = 4

Bolt = 8
Torque
FT./LBS.

Hole Size = 1-1/8

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

