

Part No: 869SV-418CSR

Schedule 80 PVC & CPVC

Clamp-On Saddle

Desc: 4X1-1/4 CPVC CLAMP SADDLE D/O SRFPT VITN

MSRP: 354.86

Part Code: 096

Weight(lbs): 2.035

Weight(kg): 0.923

Weight(gm): 923

Size: 4"X1-1/4"

Color: GRAY


Material: CPVC

Connection Double SR Fipt

Type Clamp Saddle

Hardware SS

O-Ring FKM

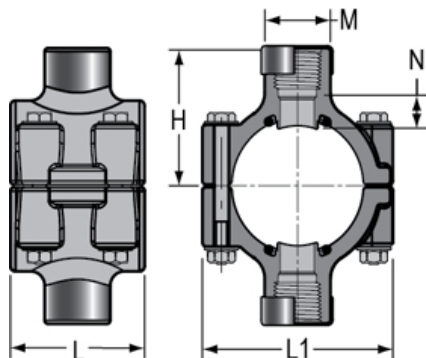

H = 4-7/32

L = 4-1/8

L1 = 5-13/16

M = 2-7/16

N = 1-1/32

Bolt = 8

Hole Size = 1-3/4

No of = 4

Bolts

Torque
FT./LBS.

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Bushing Dimension References

