

Part No: 869SV-526SR

Schedule 80 PVC & CPVC

Clamp-On Saddle

Desc: 6X1-1/4 PVC CLAMP SADDLE D/O SRFPT FKM

MSRP: 351.76

Part Code: 086

Weight(lbs): 3.799

Weight(kg): 1.723

Weight(gm): 1723

Size: 6"X1-1/4"

Color: GRAY


Material: PVC

Connection Double SR Fipt

Type Clamp Saddle

Hardware SS

O-Ring FKM

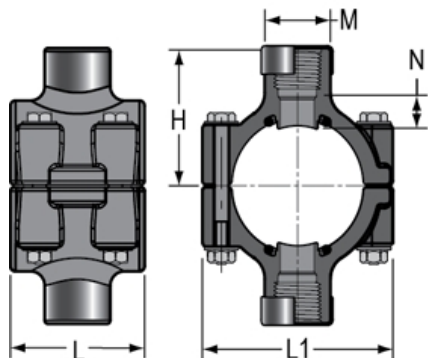

H = 5-3/4

L = 4-1/8

L1 = 8-3/16

M = 3-1/32

N = 1-7/16

Bolt = 10

Hole Size = 2-1/4

No of = 4

Bolts

Torque
FT./LBS.

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Bushing Dimension References

