

Part No: 869SV-532SR

Schedule 80 PVC & CPVC

Clamp-On Saddle

Desc: 6X4 PVC CLAMP SADDLE D/O SRFPT FKM SS

MSRP: 411.01

Part Code: 086

Weight(lbs): 6.523

Weight(kg): 2.959

Weight(gm): 2959

Size: 6"X4"

Color: GRAY


Material: PVC

Connection Double SR Fipt

Type Clamp Saddle

Hardware SS

O-Ring FKM

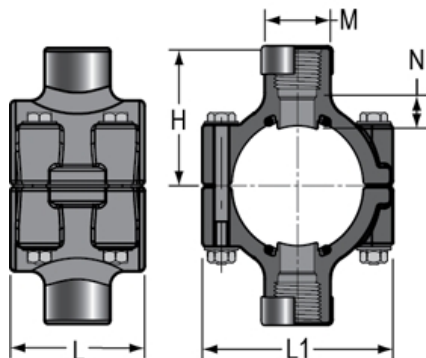

Bolt = 10
Torque
FT./LBS.

Hole Size = 4

No of = 4
Bolts

H = 6

L = 6-1/16

L1 = 9-13/16

M = 5-1/4

N = 1-3/16

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

