

Part No: 869SV-575CSR

Schedule 80 PVC & CPVC

Clamp-On Saddle

Desc: 8X1 CPVC CLAMP SADDLE D/O SRFPT FKM SS

MSRP: 1038.57

Part Code: 096

Weight(lbs): 9.244

Weight(kg): 4.193

Weight(gm): 4193

Size: 8"X1"

Color: GRAY


Material: CPVC

Connection Double SR Fipt

Type Clamp Saddle

Hardware SS

O-Ring FKM

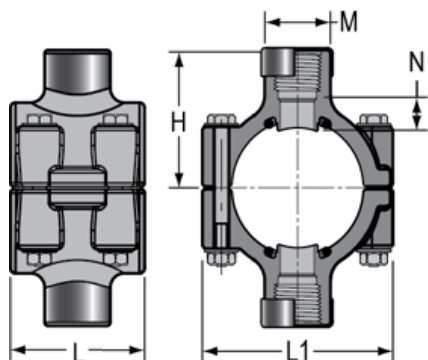

H = 6-15/16

L = 8- 1/2

L1 = 10-1/16

M = 3

N = 1-11/16

No of Bolts = 6

Bolt Torque = 10
FT./LBS.

Hole Size = 2-1/8

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Bushing Dimension References

