

Part No: 869V-248SR

Schedule 80 PVC & CPVC

Clamp-On Saddle

Desc: 2X3/4 PVC CLAMP SADDLE D/O SRFPT FKM ZNB

MSRP: 78.74

Part Code: 086

Weight(lbs): 0.739

Weight(kg): 0.335

Weight(gm): 335

Size: 2"X3/4"

Color: GRAY


Material: PVC

Connection Double SR Fipt

Type Clamp Saddle

Hardware Zinc

O-Ring FKM

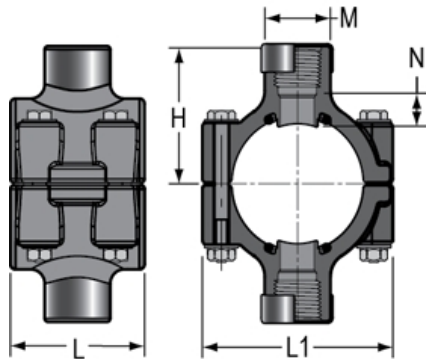

H = 2-9/16

L = 2-7/16

L1 = 3-7/16

M = 1-3/8

N = 5/8

No of Bolts = 4

Bolt Torque = 8
FT./LBS.

Hole Size = 7/8

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

