

Part No: 869V-422SR

Schedule 80 PVC & CPVC

Clamp-On Saddle

Desc: 4X3 PVC CLAMP SADDLE D/O SRFPT FKM ZN

MSRP: 152.67

Part Code: 086

Weight(lbs): 3.468

Weight(kg): 1.573

Weight(gm): 1573

Size: 4"X3"

Color: GRAY


Material: PVC

Connection Double SR Fipt

Type Clamp Saddle

Hardware Zinc

O-Ring FKM

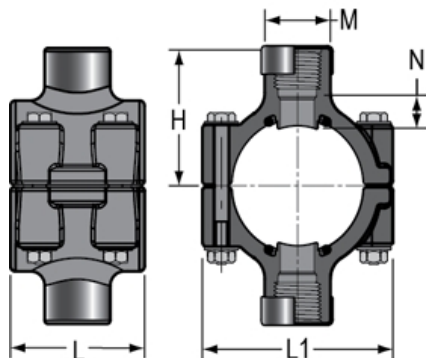

H = 5-5/32

L = 5-1/2

L1 = 5-13/16

M = 4-5/16

N = 1

Bolt = 8

Hole Size = 3

No of = 4

Bolts

Torque
FT./LBS.

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

