

Part No: 869V-527SR

Schedule 80 PVC & CPVC

Clamp-On Saddle

Desc: 6X1-1/2 PVC CLAMP SADDLE D/O SRFPT FKM

MSRP: 227.67

Part Code: 086

Weight(lbs): 3.838

Weight(kg): 1.741

Weight(gm): 1741

Size: 6"X1-1/2"

Color: GRAY


Material: PVC

Connection Double SR Fipt

Type Clamp Saddle

Hardware Zinc

O-Ring FKM

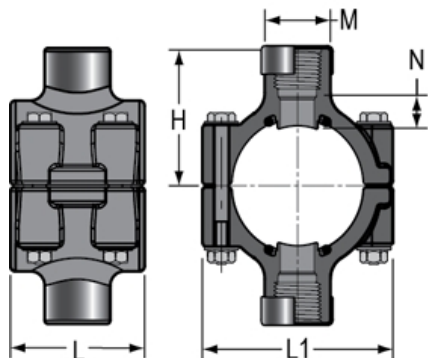

H = 5-3/4

L = 4-1/8

L1 = 8-3/16

M = 3-1/32

N = 1-7/16

No of Bolts = 4

Bolt Torque = 10
FT./LBS.

Hole Size = 2-1/4

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Bushing Dimension References

