

Part No: 869V-574SR

Schedule 80 PVC & CPVC

Clamp-On Saddle

Desc: 8X3/4 PVC CLAMP SADDLE D/O SRFPT FKM

MSRP: 461.07

Part Code: 086

Weight(lbs): 9.125

Weight(kg): 4.139

Weight(gm): 4139

Size: 8"X3/4"

Color: GRAY


Material: PVC

Connection Double SR Fipt

Type Clamp Saddle

Hardware Zinc

O-Ring FKM

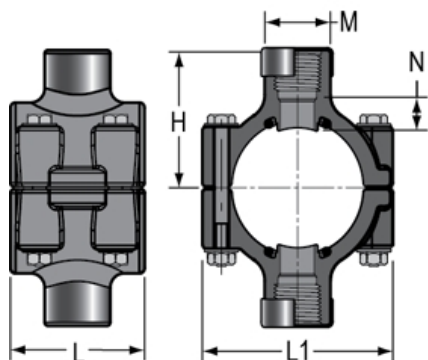

No of Bolts = 6

Bolt Torque = 10 FT./LBS.

Hole Size = 2-1/8

L = 8- 1/2

L1 = 10-1/16

M = 3

N = 1-7/8

H = 6-15/16

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Bushing Dimension References

