

Part No: 869V-577SR

Schedule 80 PVC & CPVC

Clamp-On Saddle

Desc: 8X1-1/2 PVC CLAMP SADDLE D/O SRFPT FKM

MSRP: 461.07

Part Code: 086

Weight(lbs): 8.913

Weight(kg): 4.043

Weight(gm): 4043

Size: 8"X1-1/2"

Color: GRAY


Material: PVC

Connection Double SR Fipt

Type Clamp Saddle

Hardware Zinc

O-Ring FKM

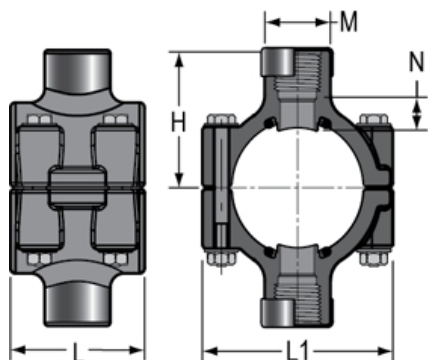

H = 6-3/4

L = 8- 1/2

L1 = 10-1/16

M = 3-1/32

N = 1-7/16

Bolt = 10

Hole Size = 2-1/8

No of = 8

Bolts

Torque
FT./LBS.

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Bushing Dimension References

