

Part No: 871-005C

Schedule 80 PVC & CPVC

Tank Adapter

Desc: 1/2 CPVC TANK ADAPTER SOCXFPT

MSRP: 81.18

Part Code: 101

Weight(lbs): 0.256

Weight(kg): 0.116

Weight(gm): 116


Size: 1/2"

Color: GRAY

Material: CPVC

Connection Socket x Fipt (Old Style)

Gasket Neoprene

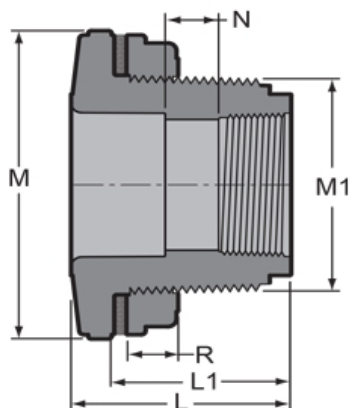

L = 2-27/32

L1 = 2-3/16

M = 2-3/8

M1 = 1-9/32

N = 1-11/32

R = 5/8

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

