

Part No: 871-010C

Schedule 80 PVC & CPVC

Tank Adapter

Desc: 1 CPVC TANK ADAPTER SOCXFPT

MSRP: 108.38

Part Code: 101

Weight(lbs): 0.344

Weight(kg): 0.156

Weight(gm): 156


Size: 1"

Color: GRAY

Material: CPVC

Connection Socket x Fipt (Old Style)

Gasket Neoprene

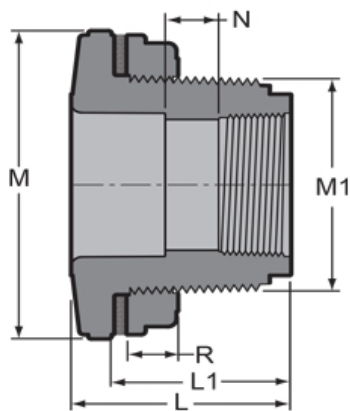

L = 2-25/32

L1 = 2- 1/8

M = 2-13/16

M1 = 1- 7/8

N = 25/32

R = 21/32

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

