

Part No: 871-040C

Schedule 80 PVC & CPVC

Tank Adapter

Desc: 4 CPVC TANK ADAPTER SOCXFPT

MSRP: 619.51

Part Code: 101

Weight(lbs): 3.377

Weight(kg): 1.532

Weight(gm): 1532


Size: 4"

Color: GRAY

Material: CPVC

Connection Socket x Fipt (Old Style)

Gasket Neoprene

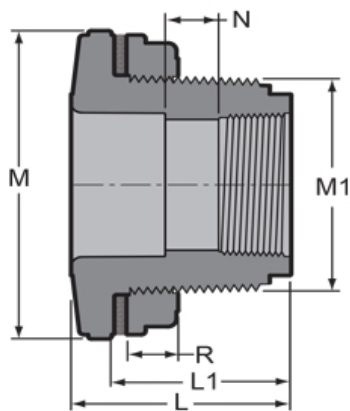

M1 = 5- 1/2

N = 1/2

R = 1- 1/4

L = 4- 7/16

L1 = 3-23/32

M = 7- 7/16

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

