

Part No: 872-007C

Schedule 80 PVC & CPVC

Tank Adapter

Desc: 3/4 CPVC TANK ADAPTER FPTXFPT

MSRP: 125.13

Part Code: 101

Weight(lbs): 0.324

Weight(kg): 0.147

Weight(gm): 147


Size: 3/4"

Color: GRAY

Material: CPVC

Connection Fipt x Fipt (Old Style)

Gasket Neoprene

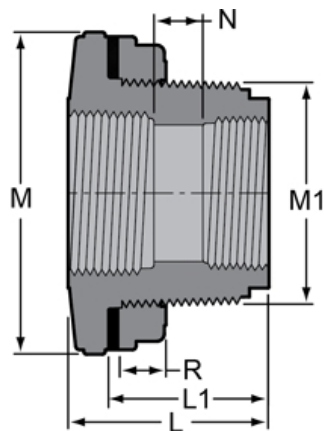

L = 2-23/32

L1 = 2-1/16

M = 2-5/8

M1 = 1-5/8

N = 1-1/4

R = 5/8

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

