

Part No: 872-020C

Schedule 80 PVC & CPVC

Tank Adapter

Desc: 2 CPVC TANK ADAPTER FPTXFPT

MSRP: 263.29

Part Code: 101

Weight(lbs): 1.448

Weight(kg): 0.657

Weight(gm): 657


Size: 2"

Color: GRAY

Material: CPVC

Connection Fipt x Fipt (Old Style)

Gasket Neoprene

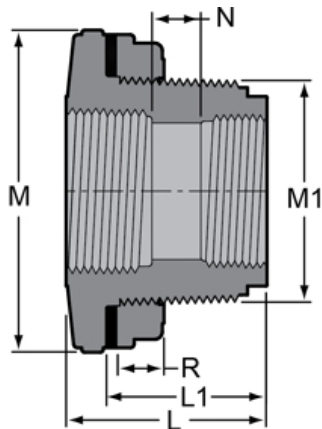

L = 3-3/16

L1 = 2-3/8

M = 5-3/32

M1 = 3-15/32

N = 1-1/8

R = 3/4

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

