

Part No: 872-040C

Schedule 80 PVC & CPVC

Tank Adapter

Desc: 4 CPVC TANK ADAPTER FPTXFPT

MSRP: 696.9

Part Code: 101

Weight(lbs): 3.472

Weight(kg): 1.575

Weight(gm): 1575


Size: 4"

Color: GRAY

Material: CPVC

Connection Fipt x Fipt (Old Style)

Gasket Neoprene

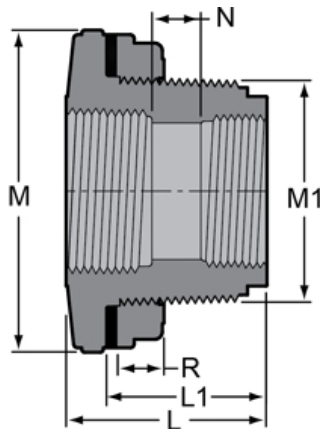

L = 4-15/32

L1 = 3-17/32

M = 7-11/16

M1 = 5- 1/2

N = 17/32

R = 1- 1/4

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

