

Part No: 8721-007

Valves

CWV Ball Valve

Desc: 3/4 PVC CWV BALL VALVE FPT EPDM

MSRP: 16.79

Part Code: 204

Weight(lbs): 0.205


Weight(kg): 0.093

Weight(gm): 93

Size: 3/4

Color: WHITE

Material: PVC

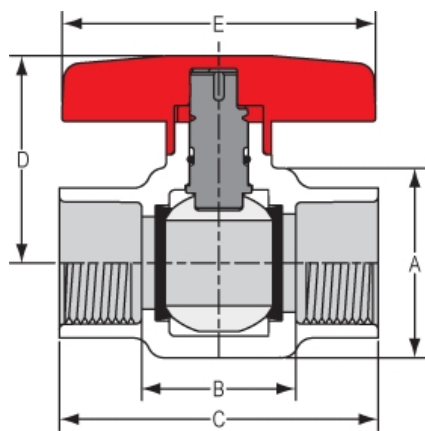

A = 1- 5/8

B = 1- 7/16

C = 2-15/16

D = 1-15/16

E = 2- 7/8

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

