

**Part No:** 875-100CF

**Fabricated Fittings**

**Wye**

**Desc:** 10 CPVC WYE SOC SCH80 100PSI G

**MSRP:** 3500.67

**Part Code:** 097

**Weight(lbs):** 73.105

**Weight(kg):** 33.16

**Weight(gm):** 33160

**Size:** 10"


**Color:** GRAY

**Material:** CPVC

**Schedule** SCH 80

**Connection** Socket X Socket X Socket

**Type** Standard

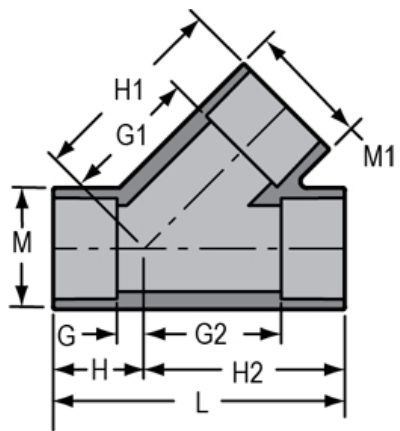

|                     |                     |                     |                      |                     |
|---------------------|---------------------|---------------------|----------------------|---------------------|
| <b>G</b> = 6- 1/2   | <b>G1</b> = 18- 7/8 | <b>G2</b> = 17- 1/4 | <b>H</b> = 11- 3/4   | <b>H1</b> = 24- 1/8 |
| <b>H2</b> = 22- 1/2 | <b>L</b> = 34- 1/4  | <b>M</b> = 11-15/16 | <b>M1</b> = 11-15/16 |                     |

## Fabricated Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

**H** = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

**L** = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

**M** = Outside diameter of socket/thread hub; ± 1/4 inch.

**N** = Socket bottom to socket bottom; couplings; ± 1/2 inch.

**W** = Height of cap; ± 1/4 inch.

## Typical Fabricated Dimension References

