

**Part No:** 875-579CF

**Fabricated Fittings**

**Wye**

**Desc:** 8X2-1/2 CPVC RED WYE SOC SCH80 100PSI G

**MSRP:** 1545.01

**Part Code:** 097

**Weight(lbs):** 18.53

**Weight(kg):** 8.405

**Weight(gm):** 8405

**Size:** 8"X8"X2-1/2"


**Color:** GRAY

**Material:** CPVC

**Schedule** SCH 80

**Connection** Socket X Socket X Socket

**Type** Reduction

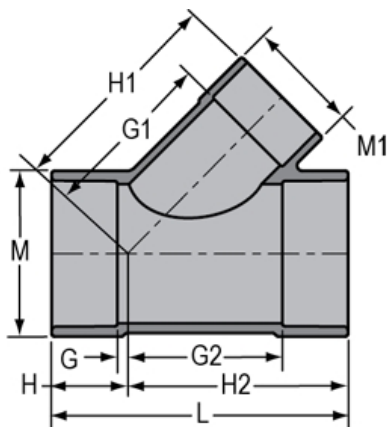

**G** = 1- 7/16

**G1** = 10-15/16

**G2** = 10- 1/16

**H** = 5-11/16

**H1** = 12-15/16

**H2** = 14- 5/16

**L** = 20

**M** = 9- 5/8

**M1** = 3- 7/16

## Fabricated Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

**H** = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

**L** = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

**M** = Outside diameter of socket/thread hub; ± 1/4 inch.

**N** = Socket bottom to socket bottom; couplings; ± 1/2 inch.

**W** = Height of cap; ± 1/4 inch.

## Typical Fabricated Dimension References

