

Part No: 878-005CSS

Schedule 80 PVC & CPVC

Adapter

Desc: 1/2 CPVC SPIGOT FEMALE ADPT SPGXSS/FPT

MSRP: 103.38

Part Code: 096

Weight(lbs): 0.099

Weight(kg): 0.045

Weight(gm): 45


Size: 1/2

Color: GRAY

Material: CPVC

Connection Spigot x SS Fipt

Type Standard

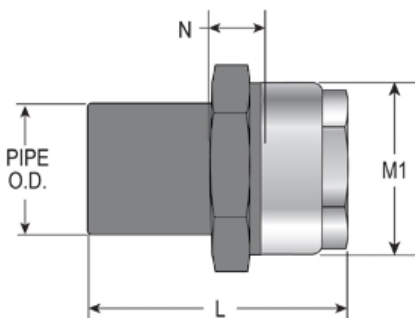

L = 1-15/16

M1 = 1-3/16

N = 15/32

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

