

Part No: 878-010SS

Schedule 80 PVC & CPVC

Adapter

Desc: 1 PVC SPIGOT FEMALE ADPT SPGXSS/FPT

MSRP: 142.38

Part Code: 086

Weight(lbs): 0.218

Weight(kg): 0.099

Weight(gm): 99


Size: 1

Color: GRAY

Material: PVC

Connection Spigot x SS Fipt

Type Standard

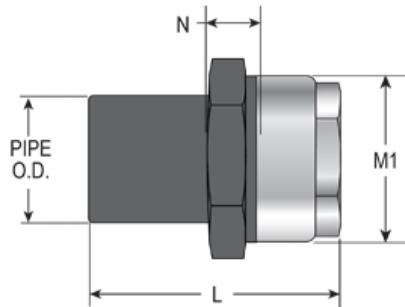

L = 2-9/32

M1 = 1-11/16

N = 7/16

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

