

Part No: 883-120C

Nipples

Nipple

Desc: 3/4X12 CPVC NIPPLE TBE SCH80

MSRP: 21.47

Part Code: 121

Weight(lbs): 0.304

Weight(kg): 0.138


Weight(gm): 138

Size: 3/4" x 12"

Color: GRAY

Material: CPVC

Nipple Type TBE (Mipt x Mipt)

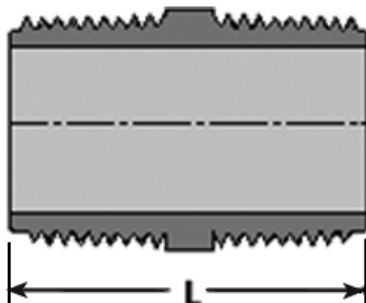

L = 12

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

