

Part No: 886-100C

Nipples

Nipple

Desc: 1-1/2X10 CPVC NIPPLE TBE SCH80

MSRP: 38.97

Part Code: 121

Weight(lbs): 0.626

Weight(kg): 0.284


Weight(gm): 284

Size: 1-1/2" x 10"

Color: GRAY

Material: CPVC

Nipple Type TBE (Mipt x Mipt)

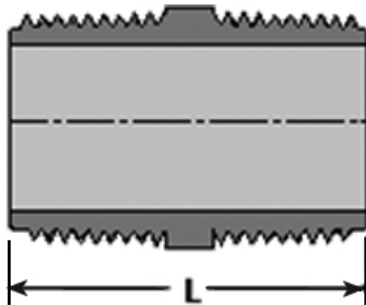

L = 10

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

