

**Part No:** 886-180C

**Nipples**

**Nipple**

**Desc:** 1-1/2X18 CPVC NIPPLE TBE SCH80

**MSRP:** 69.43

**Part Code:** 121

**Weight(lbs):** 1.127

**Weight(kg):** 0.511


**Weight(gm):** 511

**Size:** 1-1/2" x 18"

**Color:** GRAY

**Material:** CPVC

**Nipple Type** TBE (Mipt x Mipt)

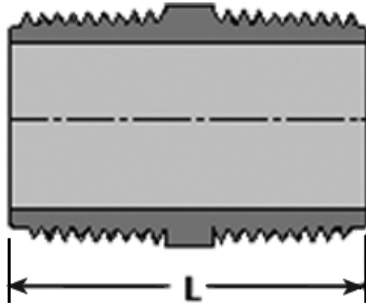

**L** = 18

## Fabricated Dimension References:

- G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses;  $\pm 1/4$  & larger  $\pm 1/2$  inch.
- H** = Intersection of center lines to face of fitting; 90° elbows, tees, crosses;  $\pm 1/4$  inch.; wyes  $\pm 1/2$  inch; 14" & larger inch.
- J** = Intersection of center lines to bottom of socket/thread; 45° elbows;  $\pm 1/4$  inch; 14" & larger  $\pm 1/2$  inch.
- L** = Overall length of fittings;  $\pm 1/2$  inch; wyes  $\pm 1$  inch; 14" & larger  $\pm 1$  inch.
- M** = Outside diameter of socket/thread hub;  $\pm 1/4$  inch.
- N** = Socket bottom to socket bottom; couplings;  $\pm 1/2$  inch.
- W** = Height of cap;  $\pm 1/4$  inch.

## Typical Fabricated Dimension References

