

Part No: 897-010BL

Low Extractable

Union

Desc: 1 PVC LE UNION SOCXSOC EPDM

MSRP: 34.26

Part Code: 065

Weight(lbs): 0.355

Weight(kg): 0.161

Weight(gm): 161

Size: 1"


Color: BLUE

Material: PVC LE

Connection Socket x Socket

Type Union

O-Ring EPDM

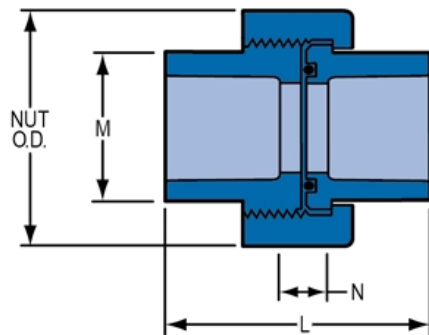

L = 2- 9/16

M = 11-7/8

N = 5/16

NUT = 2- 7/8
O.D.

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

