

Part No: 897-012C

Schedule 80 PVC & CPVC

Union

Desc: 1-1/4 CPVC UNION SOCXSOC EPDM

MSRP: 115.16

Part Code: 090

Weight(lbs): 0.523

Weight(kg): 0.237

Weight(gm): 237


Size: 1-1/4"

Color: GRAY

Material: CPVC

Connection Socket x Socket

O-Ring EPDM

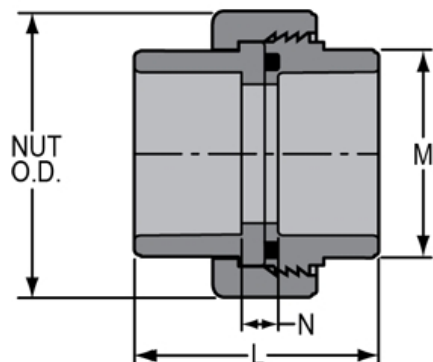

L = 2- 7/8

M = 2- 7/32

N = 11/32

NUT = 3- 5/16
O.D.

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

