

Part No: 899-007C

Schedule 80 PVC & CPVC

Union

Desc: 3/4 CPVC UNION SOCXFPT EPDM

MSRP: 90.27

Part Code: 090

Weight(lbs): 0.291


Weight(kg): 0.132

Weight(gm): 132

Size: 3/4"

Color: GRAY

Material: CPVC

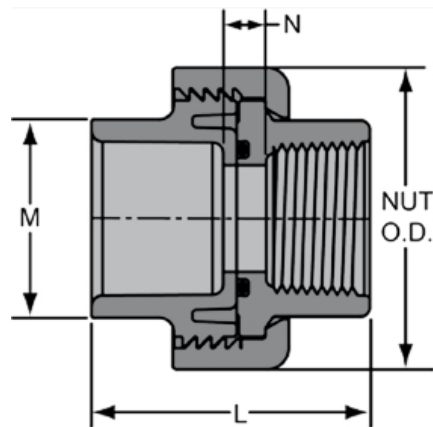

L = 2-13/32

M = 1-17/32

N = 19/32

NUT = 2- 1/2
O.D.

Connection Socket x Fipt

O-Ring EPDM

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

