

Part No: 899-010CBR

Schedule 80 PVC & CPVC

Union

Desc: 1 CPVC UNION SOCXBRFPT EPDM

MSRP: 270.07

Part Code: 096

Weight(lbs): 0.52

Weight(kg): 0.236

Weight(gm): 236


Size: 1"

Color: GRAY

Material: CPVC

Connection Socket x Brass Fipt

O-Ring EPDM

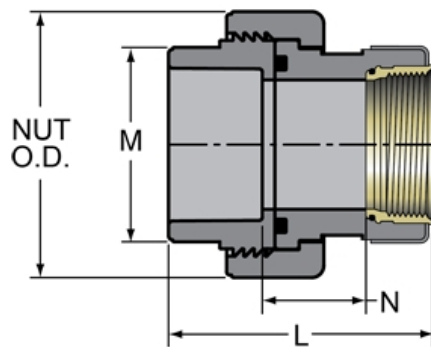

L = 2-13/16

M = 1- 7/8

N = 1- 1/32

NUT = 2- 7/8
O.D.

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

