

Part No: 899-015C

Schedule 80 PVC & CPVC

Union

Desc: 1-1/2 CPVC UNION SOCXFPT EPDM

MSRP: 237.19

Part Code: 090

Weight(lbs): 0.661


Weight(kg): 0.3

Weight(gm): 300

Size: 1-1/2"

Color: GRAY

Material: CPVC

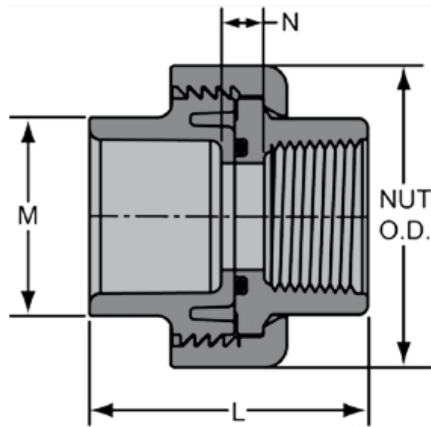

Connection Socket x Fip

O-Ring EPDM

L = 3-3/16

M = 2-9/16

N = 27/32

NUT = 3-9/16
O.D.

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

