

Part No: 899-020BR

Schedule 80 PVC & CPVC

Union

Desc: 2 PVC UNION SOCXBRFPT EPDM

MSRP: 322.27

Part Code: 086

Weight(lbs): 1.585

Weight(kg): 0.719

Weight(gm): 719


Size: 2"

Color: GRAY

Material: PVC

Connection Socket x Brass Fipt

O-Ring EPDM

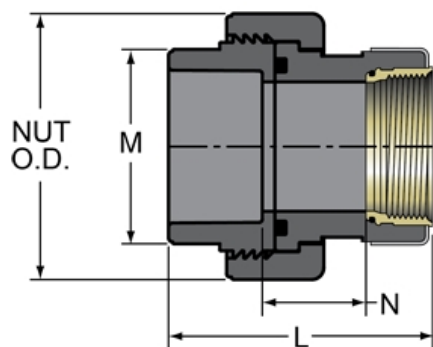

L = 3-19/32

M = 2- 7/8

N = 1-5/16

NUT = 4- 5/16
O.D.

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

