

Part No: 899-020C

Schedule 80 PVC & CPVC

Union

Desc: 2 CPVC UNION SOCXFPT EPDM

MSRP: 268.12

Part Code: 090

Weight(lbs): 1.058


Weight(kg): 0.48

Weight(gm): 480

Size: 2"

Color: GRAY

Material: CPVC

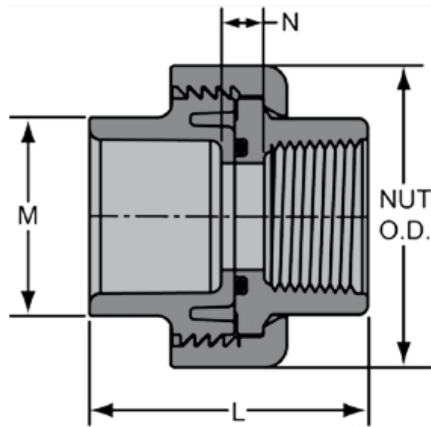

L = 3- 5/8

M = 3-1/16

N = 1-1/8

NUT = 4- 3/16
O.D.

Connection Socket x Fipt

O-Ring EPDM

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

