

Part No: 899-025

Schedule 80 PVC & CPVC

Union

Desc: 2-1/2 PVC UNION SOCXFPT EPDM

MSRP: 237.04

Part Code: 080

Weight(lbs): 1.572

Weight(kg): 0.713

Weight(gm): 713


Size: 2-1/2"

Color: GRAY

Material: PVC

Connection Socket x Fipt

O-Ring EPDM

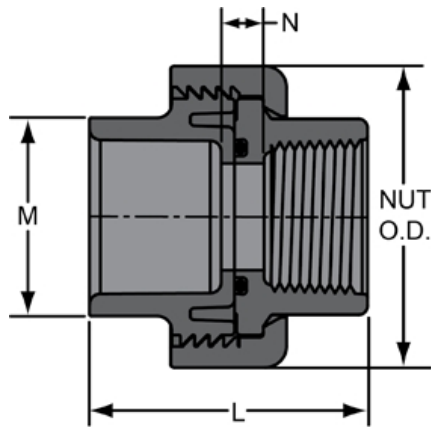

L = 4-13/32

M = 3-5/8

N = 1-13/32

NUT = 4-7/8
O.D.

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

