

Part No: BS22P6-020

Filters & Strainers

Basket Strainers

Desc: 2 PVC BASKET STRAINER SOC EPDM P6 MESH

MSRP: 1252.2

Part Code: 295

Weight(lbs): 11.228


Weight(kg): 5.093

Weight(gm): 5093

Size: 2"

Color: GRAY

Material: PVC

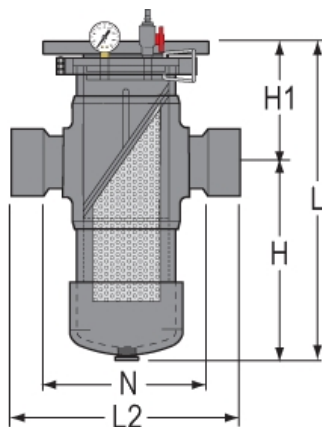

H = 10-3/4

H1 = 8

L = 18-3/4

L2 = 12- 1/8

N = 8- 5/8

Cv = 72

Values

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

