

Part No: BS22P6-120

Filters & Strainers

Basket Strainers

Desc: 12 PVC BASKET STRAINER SOC EPDM P6 MESH

MSRP: 17288.7

Part Code: 295

Weight(lbs): 236.247


Weight(kg): 107.16

Weight(gm): 107160

Size: 12"

Color: GRAY

Material: PVC

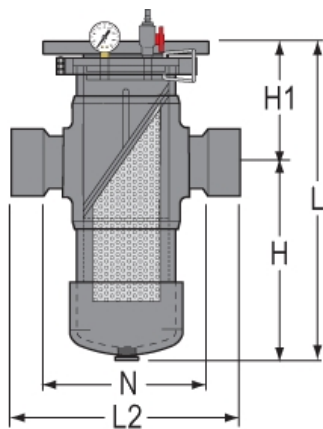

Connection Socket

O-Ring EPDM

Mesh Sieve # 6 = (1/8")

H = 34-5/16

H1 = 17-1/8

L = 52-1/2

L2 = 39-3/16

N = 26-11/16

Cv = 1063

Values

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

