

Part No: BS23C6-005C

Filters & Strainers

Basket Strainers

Desc: 1/2 CPVC BASKET STRAINR FLG EPDM C6 MESH

MSRP: 1166.24

Part Code: 297

Weight(lbs): 3.79


Weight(kg): 1.719

Weight(gm): 1719

Size: 1/2"

Color: GRAY

Material: CPVC

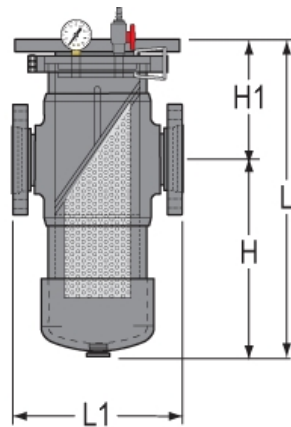

Connection Flanged

O-Ring EPDM

Mesh Sieve # 6 = (1/8")

H = 5-11/16

H1 = 4-1/2

L = 10-3/16

L1 = 8-7/8

Cv = 4.5
Values

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

