

Part No: BS23C6-025C

Filters & Strainers

Basket Strainers

Desc: 2-1/2 CPVC BASKET STRNR FLG EPDM C6 MESH

MSRP: 4304.36

Part Code: 297

Weight(lbs): 21.103


Weight(kg): 9.572

Weight(gm): 9572

Size: 2-1/2"

Color: GRAY

Material: CPVC

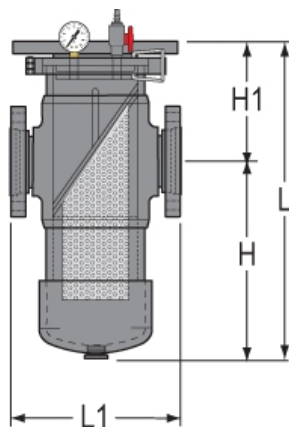

Connection Flanged

O-Ring EPDM

Mesh Sieve # 6 = (1/8")

No of Bolts = 4

Bolt Circle Dia. = 5- 1/2

Bolt Size = 5/8

H = 10-3/4

H1 = 8

L = 18-3/4

L1 = 8- 3/4

Cv = 110
Values

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

